

MCX Return Grille

SERIES	MODEL	P/N	DESCRIPTION	LISTED PRICE
NEW STYLUS, NEW STYLUS ENVI	MCX512GB, MCX512GB5, MCX518GB, MCXC12GB, MCXC18GB MCXA12GB, MCXA12GB5, MCXA18GB	028-1907	Return Grille 440 mm. (2)	350
	MCX518GB5, MCX524GB, MCX524GB5, MCXC24GB MCXA18GB5, MCXA24GB, MCXA24GB5	028-1906	Return Grille 250 mm. (1)	350
		028-1907	Return Grille 440 mm. (2)	350
	MCX530GB, MCX530GB5, MCX536GB, MCXC30GB, MCXC36GB MCXA30GB, MCXA30GB5, MCXA36GB	028-1906	Return Grille 250 mm. (2)	350
		028-1907	Return Grille 440 mm. (2)	350
	MCX536GB5, MCX042GB, MCX048GB, MCXD42GB, MCXD48GB MCXB42GB, MCXB48GB	028-1906	Return Grille 250 mm. (3)	350
		028-1907	Return Grille 440 mm. (2)	350
	MCX042GB5, MCX060GB, MCXD60GB MCXA36GB5, MCXB42GB5, MCXB60GB	028-1906	Return Grille 250 mm. (4)	350
		028-1907	Return Grille 440 mm. (2)	350
	COOL PLUS	MCX512HB, MCX512HB5, MCX518HB, MCXA12HB5	028-2109	Return Grille 300mm. (3)
MCX518HB5, MCX524HB, MCX524HB5, MCXA18HB5, MCXA24HB5		028-2109	Return Grille 300mm. (4)	350
MCX530HB, MCX536HB		028-2109	Return Grille 300mm. (2)	350
		028-2110	Return Grille 426mm. (2)	350
MCX530HB5, MCX042HB MCX048HB, MCXA30HB5, MCXB42HB, MCXB60HB,		028-2110	Return Grille 426mm. (4)	350
MCX536HB5, MCX042HB5, MCX060HB, MCXA36HB5, MCXB42HB5, MCXB60HB, MCXD60HB5		028-2109	Return Grille 300mm. (1)	350
		028-2110	Return Grille 426mm. (4)	350
DEWY	MCXE12KB, MCXE12KB5	690841250001	Return Grille (3)	350
	MCXE18KB5, MCXE24KB5	690841250001	Return Grille (4)	350
	MCXE30KB5, MCXE30KB, MCXE36KB, MCXE42KB	690841250001	Return Grille (5)	350
	MCXE36KB5, MCXE42KB5, MCXE48KB, MCXE60KB	690841250001	Return Grille (6)	350
IRIS	MYKA12SB5, MYXA18SB5	12122700000100	Return Grille (1)	500
	MYXA24SB5	12122700000096	Return Grille (2)	500
	MYXA30SB5, MYXA36SB5, MYXA42SB5	12122700000103	Return Grille MID (1)	500
		12122700000096	Return Grille LH/RH (2)	500
AQUASTYLUS	CFEB04, CFEB06	028-1907	Return Grille 440 mm. (2)	350
	CFEB08	028-1906	Return Grille 250 mm. (1)	350
		028-1907	Return Grille 440 mm. (2)	350
	CFEB10, CFEB12	028-1906	Return Grille 250 mm. (2)	350
		028-1907	Return Grille 440 mm. (2)	350
	CFEB14	028-1906	Return Grille 250 mm. (3)	350
		028-1907	Return Grille 440 mm. (2)	350
	CFEB16, CFEB20	028-1906	Return Grille 250 mm. (4)	350
		028-1907	Return Grille 440 mm. (2)	350



1

Condensate Drain Pan

SERIES	MODEL	P/N	DESCRIPTION	LISTED PRICE
NEW STYLUS **CHECK FULL MODEL**	MCX512GB, MCX512GB5, MCX518GB MCXC12GB, MCXC18GB, MCXA12GB5	362-28469+ 010-2095	Drain Pan Assy	1,500
	MCX518GB5, MCX524GB, MCX524GB5, MCXC24GB, MCXA18GB5, MCXA24GB5	362-28503+010-2101	Drain Pan Assy	1,500
	MCX530GB, MCX530GB5, MCX536GB, MCXC30GB, MCXC36GB, MCXA30GB5,	362-28550+010-2108	Drain Pan Assy	1,500
	MCX536GB5, MCX042GB, MCX048GB, MCXD42GB, MCXD48GB, MCXB48GB	362-28519+010-2113	Drain Pan Assy	1,500
	MCX042GB5, MCX060GB, MCXD60GB, MCXA36GB5, MCXB42GB5, MCXB60GB	362-28564+010-2122	Drain Pan Assy	2,000
COOLPLUS	MCX512HB5	362-32292	Drain Pan Assy	CALL
	MCX518HB5, MCX524HB5	362-32337	Drain Pan Assy	CALL
	MCX530HB5, MCX048HB	362-34208	Drain Pan Assy	CALL
	MCX042HB	362-35224	Drain Pan Assy	CALL
	MCX536HB5, MCX042HB5, MCX060HB	362-34204	Drain Pan Assy	CALL
	MCX512HB5 (SWEEP), MCXA12HB5	690317670001	Drain Pan Assy	CALL
	MCX518HB5 (SWEEP), MCX524HB5 (SWEEP), MCXA18HB5, MCXA24HB5	690317680001	Drain Pan Assy	CALL
	MCX530HB5 (SWEEP), MCX042HB (SWEEP), MCX048HB (SWEEP), MCXA30HB5, MCXB42HB, MCXB48HB	690317690001	Drain Pan Assy	CALL
MCX536HB5 (SWEEP), MCX042HB5 (SWEEP), MCX060HB (SWEEP), MCXA36HB5, MCXB42HB5, MCXB60HB	690317700001	Drain Pan Assy	CALL	
DEWY	MCXE12KB, MCXE12KB5	690835830001	Drain Pan Assy	CALL
	MCXE18KB5, MCXE24KB5	690835840001	Drain Pan Assy	CALL
	MCXE30KB, MCXE36KB, MCXE30KB5	690835850001	Drain Pan Assy	CALL
	MCXE36KB5, MCXE42KB5, MCXE60KB	690848930001	Drain Pan Assy	CALL
	MCXE42KB	690835850001	Drain Pan Assy	CALL
	MCXE48KB	690848930001	Drain Pan Assy	CALL
IRIS	MYXA12SB5, MYXA18SB5	12822700000010	Drain Pan Assy	3,000
	MYXA24SB5	12822700000011	Drain Pan Assy	3,800
	MYXA30SB5, MYXA36SB5, MYXA42SB5	12822700000009	Drain Pan Assy	4,500
AQUASTYLUS	CFEB04, CFEB06	362-28469+010-2095	Drain Pan Assy	1,500
	CFEB08	362-28503+010-2101	Drain Pan Assy	1,500
	CFEB10, CFEB12	362-28550+010-2108	Drain Pan Assy	1,500
	CFEB14	362-28519+010-2113	Drain Pan Assy	1,500
	CFEB16, CFEB20	362-28564+010-2122	Drain Pan Assy	2,000

Condensate Drain Pan

SERIES	MODEL	P/N	DESCRIPTION	LISTED PRICE	
ILLUSION#5, INSIGHT#5, ILLUSION, INSIGHT, ILLUSION ENVI, INSIGHT ENVI, INVISIBLE, HFxx WATER COIL, FCDA WATER COIL **CHECK FULL MODEL OR MEASURE THE LENGTH**	MCD009AA5, MCD012AA5, MCD012AA, MCD015AA, MCD018AA, MCD512DB, MCD518DB, MCD524DB, , MCDD12AA, MCDD18AA, MCDA12AA, MCDA12AA5, MCDA12DB, MCDA18AA, MCDA18DB MCDE12AA0, MCDE12AAP, MCDE18AA0, MCDE18AAP, HFCA04, HFCA06, HFCC04, HFCC06, HFCC08, FCDA04, FCDA06	028-0905	Drain Pan ABS Plastic Length 95 cm.	1,500	
		010-0206-001	Foam Drain Pan		
		062-12727	Condensate Drain Pan MCD		
		MCD018AA5, MCD024AA5, MCD036EB5, MCD042EB5, MCD024AA, MCD030EB, MCD030DB, MCD048DB, MCD530DB, MCDD24AA, MCDD30EB, MCDD30DB, MCDD48DB, MCDA24AA, MCDA24DB0, MCDA30DB, MCDB48DB, MCDE12AA5, MCDE24AA, MCDE30EB5, MCDE48EB, MCDE48DB, HFCC06, HFCC08, HFCC10, HFCA08, HFCA10, HFCD14, HFCD16, FCDA08, FCDA10, FCDA14, FCDA16	028-0906	Drain Pan ABS Plastic Length 110 cm.	1,500
		010-0207-001	Foam Drain Pan		
		062-12728	Condensate Drain Pan MCD		
		MCD030EB5, MCD024AA, MCD036EB, MCD036DB, MCD060DB, MCD536DB, , MCDD36EB, MCDD36DB, MCDD60DB, MCDA24AA5, MCDA24DBP, MCDA24DBP, MCDA24DBP, MCDA36DB, MCDB60DB, MCDE18AA5, MCDE24AA5, MCDE24AAP, MCDE30EBP, MCDE36DBP, MCDE36EB0, MCDE36EB5, MCDE36EBP, MCDE36DBP, MCDE42EB0, MCE42EB5, MCDE42DB0, MCDE60EBP, MCDE60DBP, HFCA08, HFCA12, HFCC12, HFCD18, HFCD20, FCDA08, FCDA12, FCDA18, FCDA20	028-0907	Drain Pan ABS Plastic Length 125 cm.	1,500
		010-0208-001	Foam Drain Pan		
		062-12729	Condensate Drain Pan MCD		
	ILLUSION PREMIUM	MCD030HB-MCD060HB	362-41147	Drain Pan Assy MCD030-060HB	CALL
			010-3217	Insu Drain Pan MCD030-060HB	
	CASSETTE TYPE	MCC518-536AB	080202250A	Drain Pan	2,000
MCC518-5361B		010-1741	Drain Pan	1,500	
MCC518-5242B, MCCE18-E242B		999-36242443	Drain Pan	4,500	
MCC530-5602B, MCCE30-602B		999-36342444	Drain Pan	CALL	
CWS03, 04		70-DRAN0004	Drain Pan (15-3710-2103004A)	2,000	
CWS06, 08, 10, 12, 14		080202250A	Drain Pan	2,000	
CWS16		690413080001	Drain Pan (15-6110-2103115)	4,500	
CWS03, 04, 06 7A		15-6113-2103100	Drain Pan	3,000	
CWS08, 10, 12, 14, 16 7A		690413080001	Drain Pan (15-6110-2103115)	4,500	
CWS04201R0FA, CWS06201R0FA		999-36242785	Drain Pan	4,500	
CWS08201R0FA, CWS10201R0FA, CWS12201R0FA, CWS14201R0FA, CWS16201R0FA		999-36242797	Drain Pan	4,500	



1

Pressure Switch



TYPE	P/N	DESCRIPTION	LIST PRICE
Low Pressure Switch	025-0448	Low Pressure Switch 27/46 PSI	1,500
High Pressure Switch	025-17620-002	High Pressure Switch 398/313 PSI	1,500

Timer Delay Relay



MODEL	P/N	DESCRIPTION	LIST PRICE
TTA ฤๅຸຸ	025-0139	Timer 3 Min. 220V	200
	024-0612	Relay LY1F 1NO1NC	300

Expansion Valve



MODEL	P/N	DESCRIPTION	LIST PRICE
FIX ORIFICE TYPE (R-22/R-407C)			
MCV090AB, SWUT090, SWUT180 SRUB080, SRUB160*, SRUB190 (1 Circuit) (025-0461)	025-0653	TGEX 7.5	3,700
MCV120AB, TTH210BD*, TTH100ED, TTH180ED*, TTH210ED*, SRUB110, SRUB190*, SRUB220* (025-0462)	025-0654	TGEX 11 067N2027	3,700
SWUT120, SWUT240* SRUB130, SRUB250*	025-0463	TRE 20-10X	4,000
SWUT060	025-0464	TCBE #2 068U4202	3,500
MCV090-120BB, TTH060BD, TTH075BD, TTH100BD, TTH120BD, TTH160BD*, TTH180BD*, TTH060ED, TTH075ED, TTH160ED*, TWE120CD, TWE160CD*, TWE180CD*, TWE240CD*, TTH075GB, TTH100GB, TTH120GB (Direct Drive)	025-0406	TXV Valve 1/2" x 7/8"	2,000
TTH240BD*, TTH120ED, TTH240ED*, TTV250* (025-0470)	025-0655	TGEX 12 067N2029	4,000
TTV250*	025-0656	TGEX 15 067N2032	4,000
TTV300*	025-0657	TGEX 18 067N2033	4,000
TTV400* (025-0471)	025-0658	TGEX 26 067N2035	5,000
TTV500*, TTV600* (025-0472)	025-0659	TGEX 30 067N2038	5,500
TTH120FD, TWE240FD* (Hi-Eff)	888-250043	TCLE 7.5 HC	5,500

หมายเหตุ * ใช้ 2 ตัว/เครื่อง

Expansion Valve



MODEL	P/N	DESCRIPTION	LIST PRICE
SERVICEABLE ORIFICE TYPE (R-22/R407c)			
TTH075BD, TTH160BD*, TWE160CD*, TTH075ED, TTH075GB (Direct Drive)	690306020001	ELEMENT TEX 5 067B3267	2,500
	690306030001	ORIFICE TEX 5-7.5 ORIFICE NO 2 067B2790	1,500
	888-250033	VALVE BODY 1/2IN X 7/8IN AN- GLE 067B4010	800
TTH100BD, TTH180BD*, TTH210BD*, TWE180CD*, TWE210CD*, TTH100ED, TTH100GB (Direct Drive)	690306020001	ELEMENT TEX 5 067B3267	2,500
	888-250032	ORIFICE TEN5-6.0 ORIFICE NO.3 067B2791	1,500
	888-250033	VALVE BODY 1/2IN X 7/8IN AN- GLE 067B4010	800
TTH120BD, TTH240BD*, TWE120CD, TWE240CD*, TTH120ED, TTH120GB (Direct Drive)	690306020001	ELEMENT TEX 5 067B3267	2,500
	690306040001	ORIFICE TEX 5-13 ORIFICE NO 4 067B2792	1,500
	888-250033	VALVE BODY 1/2IN X 7/8IN AN- GLE 067B4010	800
TTH160BD (1Circuit)	690306050001	ELEMENT TEX 12 067B3227	2,800
	888-250024	ORIFICE TEN12-11 ORIFICE NO.5 067B2708	2,000
	690306060001	VALVE BODY TE 20 7/8 x 1-1/8 067B4021 STRAIGHT WAY	1500
TTH060FD (Hi-Eff)	888-250040	TEX2 THERM. EXP VALVE FLARE/ FLARE 068Z3209	2,800
	888-250041	ORIFICE FLARE NO.05 068-2008	800

หมายเหตุ * ใช้ 2 ตัว/เครื่อง



Bearing Ball




MODEL	P/N	SIZE	LIST PRICE
TTH060-075, BDHA20-25, ESWUT060 (UC204)	029-0034-002	3/4"	1,000
TTH100, TTH120, TWE120, BDHA34, BDCB40, ESRUB080/110/130AD (UC205)	029-0033	1"	1,000
TTH160-240, TWE180-240, BDCB60-80, BDHA50-80, BDCB40, ESRUB080/110/130AD (UC206)	029-0039-001	1-3/16"	1,000

Bearing Rubber (Housing Bearing)



MODEL	P/N	SIZE	LIST PRICE
TTH060-075, BDHA20-25, ESWUT060	028-0038	3/4"	100
TTH100, TTH120, TWE120, BDHA34, BDCB40, ESRUB110-130AD	028-0039	1"	100
TTH160-240, TWE180-240, BDCB60-80, BDHA50-80, ESWUT090-240, ESRUB160-250AD	028-0040	1-3/16"	100

Bracket Bearing

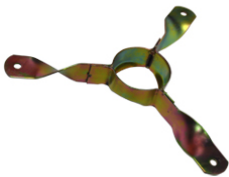

MODEL	P/N	SIZE	LIST PRICE
TWE180-240BD, BDCB60-80, ESWUT090-240, ESRUB160-250AD (3 sets/unit) (026-0093)	690875750001	Per Set	450
BDHA25, BDHA34, TTH060-TTH120 (2 sets/unit)	026-0090	Per Set	450
TWE120AD, BDCB40 (6 PCs/unit)	026-2551	Per PC	150
TTH160-180 (Size 12") (9 PCs/unit)	N/A	Per PC	
BDCB60-80, BDHA50-80, TTH210-240CD, TWE180BD, TWE210-240CD/ED (9 PCs/unit)	026-2552	Per PC	150
BDCB50-60, TWE160-TWE180CD/ED (8 PCs/unit)	026-2632	Per PC	150

Bushing Rubber



MODEL	P/N	LIST PRICE
MCW5097-5247BA00	90400091	150
MCW509-524DB5/BB (028-1821)	70-OTHR0079	100
MCW509SB5 (202730100201)	690405940001	100
MCW512SB5	70-BUSH0007	100
MCW518SB5 (202730790001)	690405930001	100
MCW524-530SB (201101090004)	690405920001	100
MCW5306B(5), MCW5366B, MCWA306B(5), MCWA366B, HWCFO3-12 (P5)	690407660001	200